




GB26T4GS, Mech Ground Conn, Cable to Bar, Galvanized Steel

By Burndy
Catalog # [GB26T4GS](#)

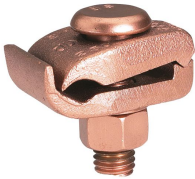

Mechanical Grounding Connector, Cable to 1/2" Thick Bar, 4 AWG (Sol)-2/0 AWG (Str), Hardware: Galvanized Steel

Features

- Mechanical Grounding Connector
- Cable to 1/2" Thick Bar
- 4 AWG (Sol)-2/0 AWG (Str)
- Galvanized Steel Hardware

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - Copper Solid Size Range	4 AWG-2/0 AWG
Conductor - Copper Str Size Range	4 AWG - 2/0 AWG
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	55.4 mm
Dimension - Height inch	2.18 in
Package Weight	0.000 lb.
Dimension - Width inch	1.56 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	24 mm
Dimension - B Length inch	1.06 in
Dimension - Width fraction	1-5/9 in
Dimension - Length Overall inch	0.94 in

Force Related

Installation Torque	240 lb-in
Recommended in-lb	

General

Physical Attribute - Screw Type	Oval Shank Bolt
Plated	N
UPC	781810196106
Material Type - Screw	Steel - Galvanized
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810196106
UPC 14 Digit GTIN	00781810196106

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)