


GB29CG40, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GB29CG40](#)

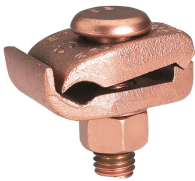

Mechanical Ground Connector

Features

- Accepts Cable 2/0 Solid to 250 kcmil

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Solid Size Range	2/0 AWG-4/0 AWG
Conductor - Copper Str Size Range	2/0 AWG - 250 kcmil
Conductor - Copper Str Size	2/0 Sol to 250MCM

Dimensions

Package Height	0.000 in
Dimension - Height mm	58.9 mm

Dimension - Height inch	2.32 in
Package Weight	0.000 lb.
Dimension - Width inch	1.88 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	32 mm
Dimension - Width fraction	1-7/8 in
Dimension - Length Overall inch	1.25 in

Force Related

Installation Torque	40
Recommended in-lb	

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
UPC	781810422014
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810422014
UPC 14 Digit GTIN	00781810422014

Logistics

Minimum Pack Quantity	28
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)