




GB29G69, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GB29G69](#)

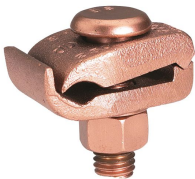

Mechanical Ground Connector

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	AWG2/0 to 250Kcmil
-----------------------------	--------------------

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.

Package Length	0.000 in
Package Width	0.000 in

Force Related

Installation Torque Recommended in-lb	480
---------------------------------------	-----

General

Plated	N
UPC	781810001790
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810001790
UPC 14 Digit GTIN	00781810001790

Logistics

Minimum Pack Quantity	24
Pallet Quantity	432
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)