


GB29G69HEX, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GB29G69HEX](#)

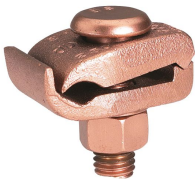

Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 2/0 AWG (Sol) -250 kcmil, 1/2" Stud, 1.5 IN Width.

Features

- Mechanical Grounding Connector
- Cable to 1/4" Thick Bar
- 2/0 AWG (Sol)-250 kcmil
- 1/2" Stud

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Solid Size Range	2/0 AWG - 250 kcmil
Conductor - Copper Str Size Range	2/0 AWG-250 kcmil
Conductor - Copper Str Size	• 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - Height mm	44 mm
Length	1.96 in
Dimension - Height inch	1.75 in
Package Weight	0.000 lb.
Dimension - Width inch	1.96 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	38 mm
Height	1.75 in
Width	1.5 in
Dimension - Width fraction	1-24/25 in
Dimension - Length Overall inch	1.50 in
Dimensions	1.96 in x 1.5 in x 1.75 in

Force Related

Installation Torque	480 lb-in
Recommended in-lb	

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
UPC	781810053904
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810053904
UPC 14 Digit GTIN	00781810053904

Logistics

Pallet Quantity	2880
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)