




BURNDY

GB29G69HEXT8, Mechanical Grounding Connector, Cable to Bar

By Burndy

Catalog # [GB29G69HEXT8](#)

Mechanical Grounding Connector, Cable to 1" Thick Bar, 2/0 AWG (Sol) -250 kcmil, 1/2" Stud, 1.5 IN Width.

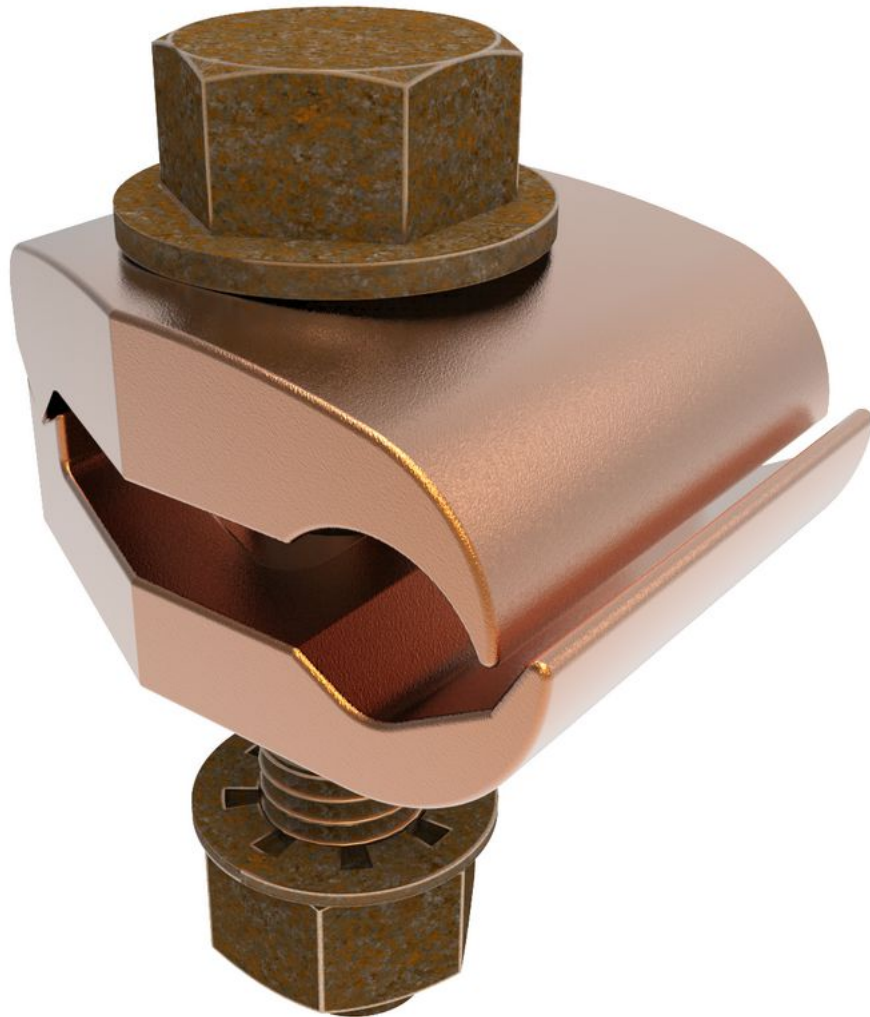

Features

- Mechanical Grounding Connector
- Cable to 1" Thick Bar
- 2/0 AWG (Sol)-250 kcmil
- 1/2" Stud

Specifications

Certification - ETL

No

Certification - UL Recognized

No

Standards - Industry Standards Met
UL467
Standards - RoHS Compliance Status
EX
Certification - cULus
No
Certification - UL Listed Direct Burial
Yes
Industry Standard(s)
UL467
UL Listed
No
Certification - CSA Approved
No

Conductor

Conductor - Copper Solid Size

- 2/0 AWG
- 3/0 AWG
- 4/0 AWG

Conductor - Copper Solid Size Range
2/0 AWG - 250 kcmil
Conductor - Copper Str Size Range
2/0 AWG - 250 kcmil
Conductor - Copper Str Size

- 2/0 AWG
- 3/0 AWG
- 4/0 AWG
- 250 kcmil

Dimensions

Package Height
0.000 in
Dimension - Height mm
44 mm
Length
1.96 in
Dimension - Height inch
1.75 in
Package Weight
0.000 lb.
Dimension - Width inch
1.96 in
Package Length
0.000 in
Package Width
0.000 in
Dimension - L Length Overall mm
38 mm
Height
2.75 in
Width
1.5 in
Dimension - Width fraction
1-24/25 in
Dimension - Length Overall inch
1.50 in
Dimensions
1.96 in x 1.5 in x 2.75 in

Force Related

Installation Torque Recommended in-lb
480 lb-in

General

Physical Attribute - Screw Type
Hexagonal Bolt
Plated
N
UPC
781810458617
Material Type - Screw

DURIUM™ Silicon Bronze
Material
Copper Alloy
Plating Type
Unplated
UPC 12 Digit
781810458617
UPC 14 Digit GTIN
00781810458617

Logistics

Minimum Pack Quantity
28
Pallet Quantity
2160
Carton Quantity
12

Product Assets

[Catalog \[English\]](#)



A Hubbell brand
© 2026 Hubbell Incorporated. All rights reserved
BRDY_CA-GB29G69HEXT8-SPEC-EN | REV 5/2026