




GB34T10W, Mech Ground Conn, Cable to Bar, Tin Plated

By Burndy
Catalog # [GB34T10W](#)

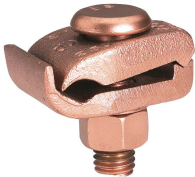

Mechanical Grounding Connector, Cable to 1/4" - 1 1/4" Thick Bar, 300 kcmil - 500 kcmil, 1/2" Stud, 2-3/8" Width, Hot Tin Dipped

Features

- Mechanical Grounding Connector
- Cable to 1/4"-1 1/4" Thick Bar
- 300-500 kcmil
- 1/2" Stud
- Hot Tin Dipped

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size Range	300 KCMIL - 500 KCMIL
Conductor - Copper Str Size Range	300 kcmil - 500 kcmil
Conductor - Copper Str Size	• 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	90.7 mm
Dimension - Height inch	3.57 in
Package Weight	0.000 lb.
Dimension - Width inch	2.31 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	35 mm
Dimension - Width fraction	2-1/3 in
Dimension - Length Overall inch	1.38 in

Force Related

Installation Torque	480 lb-in
Recommended in-lb	

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	Y
UPC	781810117644
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy
Plating Type	Tin - Hot Dipped
UPC 12 Digit	781810117644
UPC 14 Digit GTIN	00781810117644

Logistics

Minimum Pack Quantity	1
Pallet Quantity	2352
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)