




GBG28G1, Mechanical Grounding Connector, Cutout Extension

By Burndy
Catalog # [GBG28G1](#)

Cutout Extension

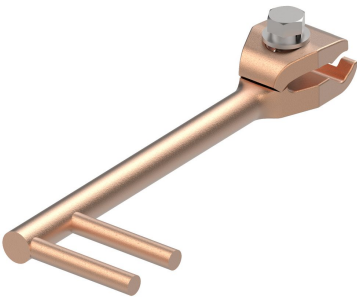

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

- 3/0 AWG
- 4/0 AWG

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Dimension - Width inch	7.12 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.19 in
Dimension - Width fraction	7-1/8 in

Conductor

Conductor - Copper Solid Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Solid Size Range	4 AWG-4/0 AWG
Conductor - Copper Str Size Range	4 AWG - 4/0 AWG
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
UPC	781810096208
Material Type - Screw	Steel - Stainless
Plating Type	Unplated
UPC 12 Digit	781810096208
UPC 14 Digit GTIN	00781810096208

Logistics

Minimum Pack Quantity	1
Pallet Quantity	600
Carton Quantity	2

Product Assets

[Catalog \[English\]](#)



A Hubbell brand