




GBL30, Mechanical Grounding Connector, Cable to Bar

By Burndy

Catalog # [GBL30](#)

Cast Copper Alloy Ground Connector, 4 AWG (Sol) - 300 kcmil, 1/2"
Stud, 1-1/2" Width

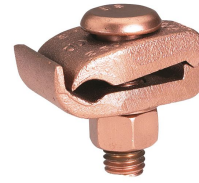

Features

- High copper alloy ground connector for joining a range of cable to 1/4" thick bar
- One-wrench installation
- Suitable for Direct Burial in earth or concrete

Application

For Copper Cable To Bar, Direct Burial Cable

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil
Conductor - Copper Solid Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Solid Size Range	4 AWG - 300 KCMIL
Conductor - Copper Str Size Range	4 AWG - 300 kcmil



Dimensions

Package Height	0.000 in
Dimension - Height mm	58.9 mm
Dimension - Height inch	2.32 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	48 mm
Dimension - Hole Size inch	0.56 in
Dimension - Stud Size inch	33/64
Dimension - Width mm	38 mm
Dimension - Width inch	1.50 in
Dimension - Bus Thickness inch	0.32 in
Dimension - Length Overall inch	1.88 in

Force Related

Installation Torque Recommended	480 lb-in
---------------------------------	-----------

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Material - Hardware	DURIUM™ Silicon Bronze
Physical Attribute - Screw Type	Hexagonal Bolt
Plated	No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810001844
Type	GBL
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810001844
UPC 14 Digit GTIN	00781810001844

Logistics

Minimum Pack Quantity	1
Pallet Quantity	2688
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)