


GBM34, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GBM34](#)

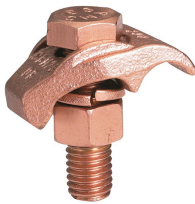

Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 300 kcmil - 500 kcmil, 1/2" Stud

Features

- High copper alloy ground connector for joining a range of cable to 1/4" thick bar
- Type GBM clamps cable directly on bar surface
- One-wrench installation
- UL467 Listed
- Suitable for Direct Burial in earth or concrete

Application

For Copper Cable To Bar, Direct Burial Cable

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil
Conductor - Copper Solid Size Range	300 KCMIL - 500 KCMIL
Conductor - Copper Str Size Range	300 kcmil - 500 kcmil

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - Height mm	58.9 mm
Dimension - Height inch	2.32 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	35 mm
Dimension - Width fraction	2-2/9 in
Dimension - Width mm	56 mm
Dimension - Width inch	2.22 in
Dimension - Length Overall inch	1.38 in

Force Related

Installation Torque Recommended	480 lb-in
---------------------------------	-----------

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Material Type - Screw	DURIUM™ Silicon Bronze
Physical Attribute - Screw Type	Hexagonal Bolt
Plated	No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810231463
Type	GBM
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810231463
UPC 14 Digit GTIN	00781810231463

Logistics

Minimum Pack Quantity	1
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)