


GBM4C, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GBM4C](#)

Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 8 AWG (Sol)-
4 AWG (Str), 3/8" Stud

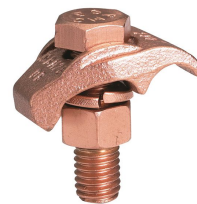

Features

- High copper alloy ground connector for joining a range of cable to 1/4" thick bar
- Type GBM clamps cable directly on bar surface
- One-wrench installation
- UL467 Listed
- Suitable for Direct Burial in earth or concrete

Application

For Copper Cable To Bar, Direct Burial Cable

Specifications

Buy American Compliant	Contact Manufacturer
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 8 AWG
	• 7 AWG
	• 6 AWG
	• 5 AWG
	• 4 AWG
Conductor - Copper Solid Size	• 8 AWG
	• 7 AWG
	• 6 AWG
	• 5 AWG
	• 4 AWG
Conductor - Copper Solid Size Range	#8 AWG-#4 AWG
Conductor - Copper Str Size Range	8 AWG - 4 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	34.5 mm
Dimension - Height inch	1.36 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	22 mm
Dimension - Width fraction	1-1/50 in
Dimension - Width mm	26 mm
Dimension - Width inch	1.02 in
Dimension - Length Overall inch	0.88 in

Force Related

Installation Torque Recommended	240 lb-in
in-lb	

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Material Type - Screw	DURIUM™ Silicon Bronze
Physical Attribute - Screw Type	Hexagonal Bolt
Plated	No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810231432
Type	GBM
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810231432
UPC 14 Digit GTIN	00781810231432

Logistics

Minimum Pack Quantity	1
Pallet Quantity	15000
Carton Quantity	150

Product Assets

[Catalog \[English\]](#)