




GBM4CT4, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GBM4CT4](#)

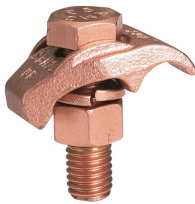

Mechanical Grounding Connector, Cable to 1/4" - 1/2", Thick Bar, 8 AWG (Sol)- 4 AWG (Str), 3/8" Stud.

Features

- High copper alloy ground connector for joining a range of cable to 1/4" thick bar
- Type GBM clamps cable directly on bar surface
- One-wrench installation
- UL467 Listed, Suitable for Direct Burial in earth or concrete

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG
Conductor - Copper Solid Size Range	#8 AWG-#4 AWG
Conductor - Copper Str Size Range	8 AWG - 4 AWG
Conductor - Copper Str Size	• 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	34.5 mm
Dimension - Height inch	1.36 in
Package Weight	0.000 lb.
Dimension - Width mm	26 mm
Dimension - Width inch	1.02 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	22 mm
Dimension - Width fraction	1-1/50 in
Dimension - Length Overall inch	0.88 in

Force Related

Installation Torque	240 lb-in
Recommended in-lb	

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
UPC	781810042793
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810042793
UPC 14 Digit GTIN	00781810042793

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)