



GC2525CTHEX314, Mech Ground, One to Two Cables to Bar

By Burndy
Catalog # [GC2525CTHEX314](#)

Mechanical Cable Tray Ground Clamp, 1 to 2 Cables to Bar, #6 Sol-1/0 Str Cu/Al, 3/8" Galvanized Steel Hardware

Features


- Cable Tray Ground Clamp
- Accommodates #6 Sol-1/0 Str Cable (Copper or Aluminum)
- 3/8" Galvanized Steel Hardware

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - Copper Solid Size Range	6 AWG-1/0 AWG
Conductor - AL Str Size	• 6 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG
Conductor - AL Str Size Range	6 AWG-1/0 AWG
Conductor - Copper Str Size Range	6 AWG - 1/0 AWG

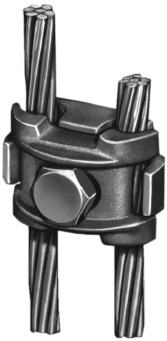

Conductor - Copper Str Size	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
-----------------------------	---

Dimensions

Package Height	0.000 in
Dimension - Height mm	49.5 mm
Dimension - Height inch	1.95 in
Package Weight	0.000 lb.
Dimension - Width mm	37 mm
Dimension - Width inch	1.45 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.12 in
Dimension - Cross Flats inch	0.56 in

Force Related

Installation Torque Recommended in-lb	240 LBS/in
---------------------------------------	------------

General

Plated	Y
UPC	781810093443
Material	Copper Alloy
Plating Type	Tin
UPC 12 Digit	781810093443
UPC 14 Digit GTIN	00781810093443

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1800
Carton Quantity	50

Product Assets

[Catalog \[English\]](#)