


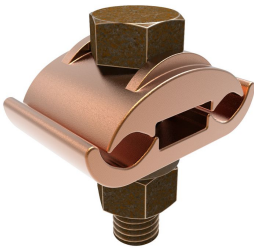

GC2929, Mechanical Grounding Connector, Two Cables to Bar

By Burndy
Catalog # [GC2929](#)

Mechanical Grounding Connector, 2 Cables to 1/4" Thick Bar, 2/0 AWG (Sol) -250 kcmil, 1/2" Stud,Torque:480 lb in



Features

- High copper alloy ground connector for joining a wide range of 2 parallel cables to 1/2" thick bar
- Type GC separates cable from bar
- Type GCM clamps cable direct to bar surface
- One wrench installation
- UL467 Listed
- Suitable for Direct Burial in earth or concrete

Application

For Joining A Wide Range Of Two Parallel Copper Cables, Direct Burial In Concrete Or Ground

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil
Conductor - Copper Solid Size	• 2/0 AWG • 3/0 AWG • 4/0 AWG
Conductor - Copper Solid Size Range	2/0 AWG - 250 KCMIL
Conductor - Copper Str Size Range	2/0 AWG-250 kcmil

Dimensions

Package Height	0.000 in
Dimension - Height mm	58.9 mm
Dimension - Height inch	2.32 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	32 mm
Width	2.04 in
Dimension - Width fraction	2 in
Length	1.25 in
Dimension - Width mm	52 mm
Dimension - Width inch	2.04 in
Height	2.32 in
Dimension - Length Overall inch	1.25 in
Dimensions	1.25 in x 2.04 in x 2.32 in

Force Related

Installation Torque	480 lb-in
Recommended in-lb	

General

Material Type - Screw	DURIUM™ Silicon Bronze
Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
Sub Brand	MECHANICAL CONNECTOR
UPC	781810231722
Type	GC
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810231722
UPC 14 Digit GTIN	00781810231722

Logistics

Pallet Quantity	2400
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)