


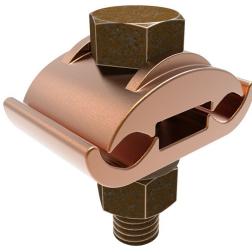

GC2929T12, Mech Ground, Two Cables to Bar, Tin Plated

By Burndy
Catalog # [GC2929T12](#)

Mechanical Ground Connector; 2 Cables to Bar, 1-1/2" Thick Bar, 2/0 AWG Sol-250 kcmil, 1/2" Stud



Features

- Mecanhical Grounding Connector
- 2 Cables to 1-1/2" Thick Bar
- 2/0 AWG Sol-250 kcmil
- 1/2" Stud

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	#2 AWG - 250 kcmil
-------------------------------	--------------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Plated	N
UPC	781810526415
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810526415
UPC 14 Digit GTIN	00781810526415

Logistics

Minimum Pack Quantity	200
Pallet Quantity	2400
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)