



GC6328RB, Ground Clamp to Rebar, 3/8" SS Hardware

By Burndy
Catalog # [GC6328RB](#)

Low Profile Ground Clamp to Rebar, Accepts Rebar Sizes #3, #4, #5 with conductor of #8 Sol-4/0 Str, For Rebar Size #6, Conductor Range #2 Sol-4/0 Str

Features

- Cast copper alloy body with stainless steel hardware
- Low profile design perfect for tight spots
- Use to connect copper grounding conductor to rebar
- Copper Conductor Range: #8 Sol to 4/0 Str
- Rebar Range: #3 to #6
- cULus Listed 467 Grounding and Bonding
- Rated for Direct Burial in Earth or Concrete

Application


Low profile range taking wire to rebar ground clamp for copper-to-rebar connections.

Specifications

Industry Standard(s)	• cULus Listed 467 Grounding and Bonding • Rated for Direct Burial in Earth or Concrete
----------------------	---

Conductor

Conductor - Rebar Size Range	#3 to #6
------------------------------	----------

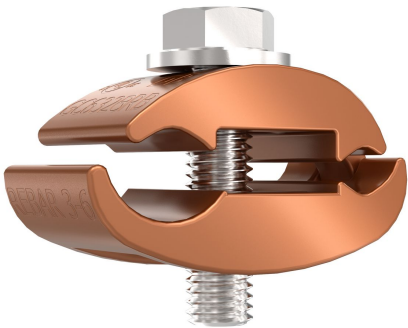

Conductor - Copper Str Size Range	#8 Sol to 4/0 Str
-----------------------------------	-------------------

Dimensions

Height	1.743 in
Width	1.125 in
Package Height	0.000 in
Length	2 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimensions	2 in x 1.125 in x 1.743 in

General

UPC	621945708839
Material - Bolt	Stainless Steel Hardware
Material	Cast Copper Alloy

Logistics

Carton Quantity	50
-----------------	----

Product Assets

[Catalog \[English\]](#)