


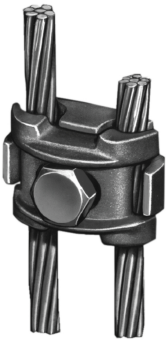

GCM34T8, Mechanical Grounding Connector, 2 Cables to Bar

By Burndy
Catalog # [GCM34T8](#)

Mechanical Ground Connector; 2 Cables to Bar, Accommodates Bar 1/2" to 1" Thick, 300-500 kcmil Copper Cable



Features

- High copper alloy ground connector for joining a wide range of 2 parallel cables to 1/2" thick bar
- Type GC separates cable from bar
- Type GCM clamps cable direct to bar surface
- One wrench installation
- UL467 Listed
- Suitable for Direct Burial in earth or concrete

Specifications

Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes

Certification - CSA Approved No

Dimensions

Dimension - Height mm 0 mm

General

Plated	N
UPC	621945457607
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	621945457607
UPC 14 Digit GTIN	00621945457607

Logistics

Minimum Pack Quantity 20

Product Assets

[Catalog \[English\]](#)