




GCS29HEX, CONSTRICTOR Ground Clamp to Steel Connector

By Burndy
Catalog # [GCS29HEX](#)

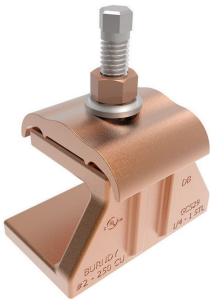

The CONSTRICTOR® Mechanical Ground Connector to Steel; #2
AWG - 250 kcmil; 1/4" - 1" Steel

Features

- Easy and simple hex tooling installation
- No hot work permit or drilling required
- Versatile, allows parallel or perpendicular conductor orientation
- Accepts beam thickness .125 - 1.000" (1/8 to 1")
- Conductor range from #6 AWG to 500 kcmil
- UL467 Listed
- Rated for Direct Burial in earth or concrete

Application

Structural Steel Grounding, I-beam, Lattice Tower Grounding

Specifications

Buy America(n) Qualified Contact Manufacturer

Conductor

Conductor Range #2 - 250 kcmil

Dimensions

Height	3.45 in
Width	1.75 in
Package Height	0.000 in
Length	3 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimensions	3 in x 1.75 in x 3.45 in

General

UPC	621945544093
Material - Hardware	Stainless Steel
Material	Cast copper alloy

Logistics

Pallet Quantity	1
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)