



# GCS34HEX, CONSTRICTOR Mechanical Ground Connector to Steel

By Burndy  
Catalog # [GCS34HEX](#)

"The CONSTRICTOR® Mechanical Ground Connector to Steel;  
250-500 kcmil Copper; 1/2" - 1" Steel"

## Features

- Easy and simple hex tooling installation
- No hot work permit or drilling required
- Versatile, allows parallel or perpendicular conductor orientation
- Accepts beam thickness 1/2" to 1" thick
- Conductor range from 250 to 500 kcmil
- UL467 Listed
- Rated for Direct Burial in earth or concrete

## Application

Structural Steel Grounding, I-beam, Lattice Tower Grounding


## Specifications

Buy America(n) Qualified      Contact Manufacturer

## Conductor

Conductor Range      250-500 Kcmil

## Dimensions

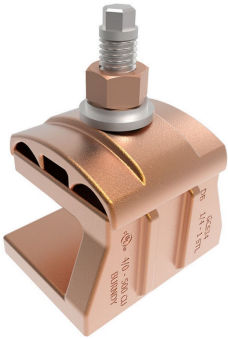

|                |                       |
|----------------|-----------------------|
| Height         | 4 in                  |
| Width          | 2.25 in               |
| Package Height | 0.000 in              |
| Length         | 3 in                  |
| Package Weight | 0.000 lb.             |
| Package Length | 0.000 in              |
| Package Width  | 0.000 in              |
| Dimensions     | 3 in x 2.25 in x 4 in |

## General

|                     |                   |
|---------------------|-------------------|
| UPC                 | 621945544086      |
| Material - Hardware | Stainless Steel   |
| Material            | Cast copper alloy |

## Logistics

|                 |     |
|-----------------|-----|
| Pallet Quantity | 240 |
| Carton Quantity | 15  |

## Product Assets

[Catalog \[English\]](#)