




GIE2CG3, Mechanical Grounding Connector for Flexible Rubber Sheath Cable, 6-2 AWG

By Burndy
Catalog # [GIE2CG3](#)

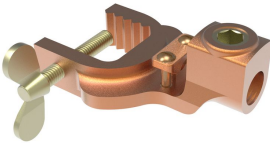

Mechanical Grounding Connector, For Flexible Rubber Sheath Cable, 6 AWG - 2 AWG

Features

- Accommodates Flexible Rubber Sheath Cable from #6 to #2 Conductor

Application

For Used To Accommodates Flexible Rubber Sheath Cable Ranging From #6 - #2 Conductors

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
EU RoHS Indicator	Yes
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Size	#6 AWG - #2 AWG
----------------	-----------------

Dimensions

Package Height	0.000 in
Dimension - Height mm	0 mm

Package Weight	0.000 lb.
Dimension - Width mm	78 mm
Dimension - Width inch	3.06 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - Length Overall	4.31 in
inch	

General

Plated	N
Sub Brand	MECHANICAL CONNECTOR
UPC	781810052297
Type	GIE-G
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810052297
UPC 14 Digit GTIN	00781810052297

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)