

GK6426, Cu Alloy Ground Clamp, 3 Cables to Rod or Pipe

By Burndy
Catalog # [GK6426](#)

3 Cables to Rod or Pipe, 4 AWG (ol. - 2/0 AWG Str., 3/8" Pipe, 5/8" - 3/4" Rod, 3/8" Stud

Features

- Rated for Direct Burial in earth or concrete
- UL467 Listed for the US and Canadian Markets
- One-wrench installation

Application

For Joining Three Equal Copper Cables To Rod Or Tube, Direct Burial In Earth Or Concrete

Specifications


Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rod Size	• 5/8 in • 3/4 in
Conductor Size	#4 AWG Sol - 2/0 AWG Str

Dimensions

Package Height	0.000 in
Dimension - Height mm	71.4 mm
Dimension - Height inch	2.81 in
Package Weight	0.000 lb.
Package Length	0.000 in

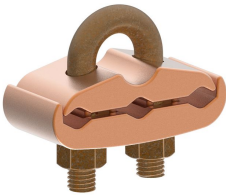

Package Width	0.000 in
Bolt Size	3/8 in
Dimension - Width mm	75 mm
Dimension - Width inch	2.94 in
Dimension - B Length inch	1.50 in

Force Related

Installation Torque Recommended in-lb	240 LBS/in
---------------------------------------	------------

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Ground Rod/Pipe/Tube (GAR/GD/GK)>Three Conductor (GK)
Material Type - Screw Plated	DURIUM™ Silicon Bronze No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810233528
Type	Three Cables to Rod or Tube
U Bolt Type	269
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810233528
UPC 14 Digit GTIN	00781810233528

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)