




GL2929CG13, Mech Ground Conn, 2 Copper Cables to Bar

By Burndy
Catalog # [GL2929CG13](#)

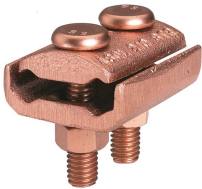

2 Copper Cables to Bar, Accommodates 2/0 Sol to 250 kcmil, Direct Burial

Features

- Accommodates 2/0 Sol - 250 kcmil Cu
- Suitable for Direct Burial

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.75 in
Package Width	0.000 in
Dimension - B Length inch	2.25 in

General

Plated	N
UPC	621945170292
Material	Copper
Plating Type	Unplated
UPC 12 Digit	621945170292
UPC 14 Digit GTIN	00621945170292

Logistics

Minimum Pack Quantity	3
-----------------------	---

Product Assets

[Catalog \[English\]](#)