




GL29G11, Mechanical Ground Connector, 2 Copper Cables to Bar

By Burndy
Catalog # [GL29G11](#)

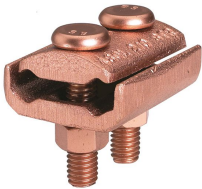

Mechanical Ground Connector; 2 Copper Cables to Bar, 2/0 AWG
Sol-250 kcmil Copper

Features

- Accommodates 2/0 Sol - 250 kcmil Cu

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Plated	N
UPC	781810055175
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810055175
UPC 14 Digit GTIN	00781810055175

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)