




GL3434T8, Mech Ground Conn, 2 Copper Cables to Bar

By Burndy
Catalog # [GL3434T8](#)

2 Copper Cables to Bar, Accommodates 300-500 kcmil Cu Cables, 1/2" to 1" Copper Bar, Direct Burial

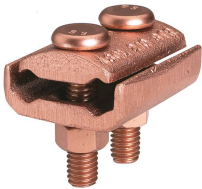

Features

- Rated for Direct Burial in earth or concrete
- UL467 Listed
- One wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	300 kcmil-500 kcmil
Conductor - Copper Str Size	• 300 kcmil • 350 kcmil • 400 kcmil • 450 kcmil • 500 kcmil

Dimensions

Dimension - Pad Width inch	1.44 in
Package Height	0.000 in
Dimension - Height mm	0 mm

Package Weight	0.000 lb.
Dimension - Width mm	73 mm
Dimension - Width inch	2.88 in
Package Length	0.000 in
Dimension - F Width Center to Center inch	1.38 in
Package Width	0.000 in
Dimension - B Length inch	2.81 in
Dimension - Length Side B inch	2.50 in
Dimension - D inch	2.56 in
Dimension - Width fraction	2-7/8 in

Force Related

Installation Torque	480 LBS/in
Recommended in-lb	

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
UPC	781810042809
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810042809
UPC 14 Digit GTIN	00781810042809

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)