



GP1726RT, Paint Penetrating Raised Floor Ground Clamp

By Burndy
Catalog # [GP1726RT](#)

Paint Penetrating Raised Floor Ground Clamp, 1 or 2 Conductors
#6-2/0 Str Copper

Features

- Accepts 1 or 2 ground conductors
- Requires less connectors to install signal reference grid
- Made of copper alloy
- Silicon bronze U-bolts, nuts and lockwashers
- Provides a low impedance ground path for maximum performance
- Grounds all pedestals (round or square)
- Accepts from 3/4" to 1" round or square
- Ease of installation
- Serves 3 needs: Signal Reference Grid, Static Ground, and Current Ground
- UL467 Listed for the US and Canadian Markets


Specifications

Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor Size	#6 AWG - 2/0 AWG STR
Number Of Conductors	• 1 • 2

Dimensions

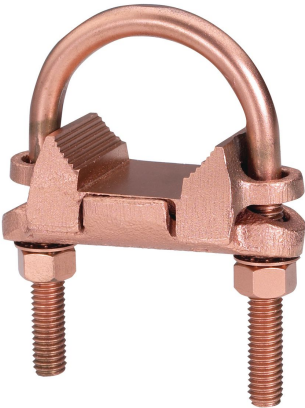

Package Height	0.000 in
Dimension - Height mm	0 mm
Dimension - Height inch	3.86 in
Package Weight	0.000 lb.
Dimension - Width mm	82 mm
Dimension - Width inch	3.22 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	38 mm
Dimension - Length Overall inch	1.50 in

General

Plated	N
Material - Hardware	DURIUM™ Silicon Bronze
Pedestal Type	• Round • Square
UPC	781810141779
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810141779
UPC 14 Digit GTIN	00781810141779

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)



A Hubbell brand