

GP6426, Mech Ground Conn, 2 Cables to Rod or Pipe

By Burndy
Catalog # [GP6426](#)

Mechanical Grounding Connector, 2 Cables to Rod or Pipe, 4 AWG (Sol.)
- 2/0 AWG (Str.), 3/8" Pipe, 5/8" - 3/4" Rod, 3/8" Stud

Features

- Rated for Direct Burial in earth or concrete
- UL467 Listed for the US and Canadian Markets
- One-wrench installation

Application

For Joining A Range Of Parallel Copper Cables Perpendicular To Rod, Pipe Or Column, Direct Burial In Earth Or Concrete

Specifications


Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rod Size Range	5/8 in - 3/4 in
Conductor - Rod Size	1/2 in
Conductor Size	#4 AWG Sol - 2/0 AWG Str
Conductor - Copper Solid Size Range	4-3/0
Conductor - Copper Str Size Range	5 AWG - 2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	63.5 mm
Dimension - Height inch	2.50 in

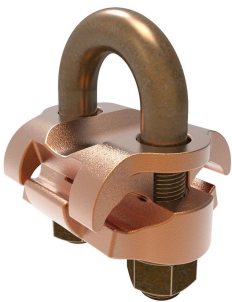

Dimension - Height fraction	2-1/2 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	43 mm
Dimension - Width fraction	2-1/8 in
Bolt Size	3/8 in
Dimension - Width mm	54 mm
Dimension - Width inch	2.12 in
Dimension - B Length inch	1.50 in
Dimension - Length Overall inch	1.69 in

Force Related

Installation Torque Recommended	240 LBS/in in-lb
---------------------------------	------------------

General

Material Type - Screw	DURIUM™ Silicon Bronze
Plated	No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810260548
Type	GP
U Bolt Type	187
Material	Copper Alloy
Plating Type	Unplated
UPC 14 Digit GTIN	00781810260548

Logistics

Minimum Pack Quantity	1
Pallet Quantity	2880
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)