




GQ291W, Copper Ground Connector, Tin Plated

By Burndy
Catalog # [GQ291W](#)

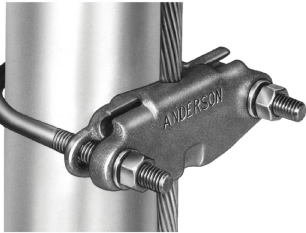

Cu Ground Connector, 2/0 AWG Str - 250 Kcmil Cu, above 6" IPS, Cable to Tube, Tin plated

Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets
- One-wrench installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Type	• CU Tube Std-Size • CU C Str-Size
Conductor - Copper Str Size Range	2/0 AWG - 250 kcmil
Conductor - Copper Str Size	• 2/0 • 3/0 • 4/0 • 250
Conductor - Copper Str Size B Range	6

Dimensions

Dimension - Height mm	173 mm
Dimension - Height inch	6.81 in
Dimension - Width mm	70 mm
Dimension - Width inch	2.75 in
Dimension - L Length Overall mm	152 mm
Dimension - Width fraction	2-3/4 in
Dimension - Length Overall inch	6.00 in

Force Related

Installation Torque Recommended in-lb	480 LBS/in
---------------------------------------	------------

General

Plated	Y
UPC	621945740112
Material Type - Screw	DURIUM™ Silicon Bronze
U Bolt Type	• 392 • 291
Material	Copper Alloy
Plating Type	Tin - Hot Dipped
UPC 12 Digit	0
UPC 14 Digit GTIN	00

Logistics

Minimum Pack Quantity	3
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)