


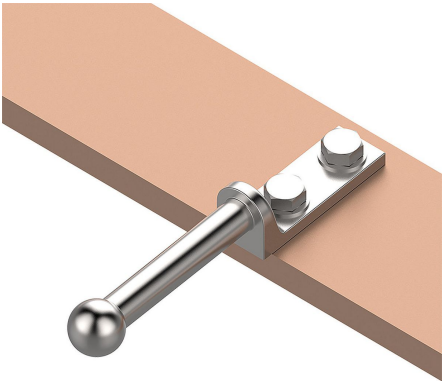

GSC752N30B, Ground Stud Connector, Tin Plated Cast Copper

By Burndy
Catalog # [GSC752N30B](#)

Temporary Protective Ground Stud, 1/2" Holes with 1.75" NEMA Spacing,
Straight Inline Pad, 30mm Ball Diameter



Features

- Constructed of Tin-Plated Cast Copper Alloy
- NEMA spaced terminal pad
- Animal mitigation / Stud Protector Cover Available
- Ball and Socket design accommodates industry standard Ground Set Clamps
- Available in Straight, 45, and 90 Degree variations
- Third-party laboratory test results available on request

Application

Grounding applications

Specifications

Buy America(n) Qualified	Contact Manufacturer
Standards - RoHS Compliance	EX
Status	
Buy American Compliant	Contact Manufacturer
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Diameter	0.56 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
General	
UPC	621945462977
Type	GROUND STUD CONNECTOR
Construction Material - Main	COPPER ALLOY
Sub Brand	Connector
Finish Type	Tin Plated Copper

Logistics

Minimum Pack Quantity	10
-----------------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)