


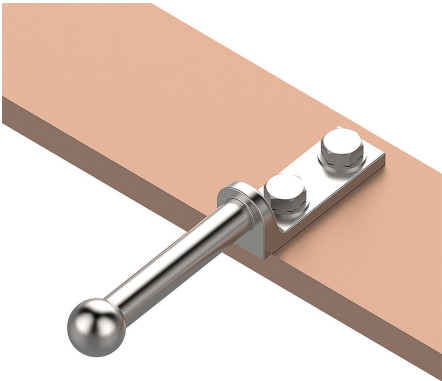

GSC752N30B45, Ground Stud Conn, Tin Plate Cast Cu, 45 Degree

By Burndy
Catalog # [GSC752N30B45](#)

Ground Stud Connector; 45 Degree Bend, 2-Hole Pad, 1/2" Holes on 1.75" Centers



Features

- Constructed of Tin-Plated Cast Copper Alloy
- NEMA spaced terminal pad
- Animal mitigation / Stud Protector Cover Available
- Ball and Socket design accommodates industry standard Ground Set Clamps
- Available in Straight, 45, and 90 Degree variations
- Third-party laboratory test results available on request

Specifications

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
----------------	----------

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

UPC	621945462953
-----	--------------

Logistics

Minimum Pack Quantity	0
Pallet Quantity	630
Carton Quantity	6

Product Assets

- [Catalog \[English\]](#)
[Catalog Page \[English\]](#)