




GSC752N30B5H, Ground Stud, Tin Cast Cu, Inline NEMA Pad

By Burndy
Catalog # [GSC752N30B5H](#)

Ground Stud, Tin Plated Cast Copper, Inline NEMA Pad, 30 mm ball stud, Grade 5H

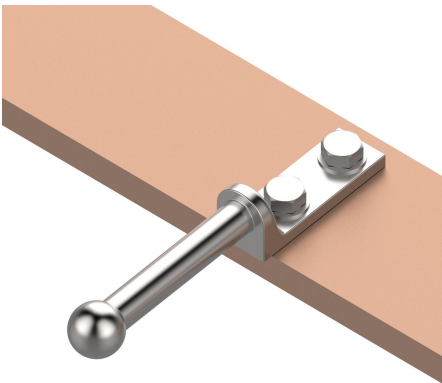

Features

- ASTM F855 Grade 5H Tested and Rated
- Third-party laboratory test results available
- 30mm Ball Stud
- Inline pad
- NEMA spacing for 1/2" Hardware
- Cast copper alloy
- Tin-plated for corrosion resistance
- Stud Cover Available - GSC75030BCOVER

Specifications

Buy America(n) Qualified Contact Manufacturer

Dimensions

Height	1.5 in
Width	1.25 in
Package Height	0.000 in
Length	8.73 in

Package Weight	0.000 lb.
Size	30mm Ball Stud
Package Length	0.000 in
Package Width	0.000 in
Dimensions	8.73 in x 1.25 in x 1.5 in

General

UPC	621945651081
Type	Safety Ground Stud
Material	Tin-Plated Copper

Logistics

Pallet Quantity	1000
Carton Quantity	100

Product Assets

- [Catalog \[English\]](#)
[Catalog Page \[English\]](#)