



GXW26C58, GROUNDWEJ Conn, Cable to Cable or Cable to Rod

By Burndy
Catalog # [GXW26C58](#)

GROUNDWEJ Connector, Groove A: 1/0-2/0; Groove B: 3/0-250 kcmil, 5/8" Copper Rod

Features


- Groove A accommodates 1/0 - 2/0
- Groove B accommodates 3/0 - 250 kcmil
- 5/8" Copper Rod

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	Yes

Conductor

Conductor - Copper Str Size A	• 1/0 • 2/0
Conductor - Copper Str Size B	• 3/0 • 4/0 • 250
Conductor - Copper Solid Size A	• 1/0 • 2/0
Conductor - Copper Solid Size B	• 3/0 • 4/0
Conductor Type	• CU C Str-Size A

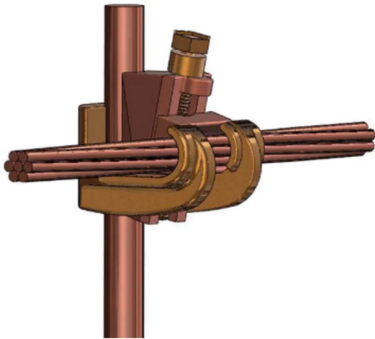

Conductor - Rod Size

- CU C Solid-Size A
- CU C Str-Size B
- CU C Solid-Size B
- Rod-Size B
- 1/2
- 5/8
- 3/4

Dimensions

Dimension - Pad Width inch	2.80 in
Dimension - Height mm	0 mm
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	781810113288
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810113288
UPC 14 Digit GTIN	00781810113288

Logistics

Minimum Pack Quantity	20
-----------------------	----

Product Assets

- [Catalog \[English\]](#)
[Installation Manual \[English\]](#)