




GXW29C58, GROUNDWEJ Conn, Cable to Cable or Cable to Rod

By Burndy
Catalog # [GXW29C58](#)

GROUNDWEJ Connector, Groove A: 4/0-250 kcmil Cu, Groove B: 4/0-250 kcmil Cu, 5/8" Copper Rod

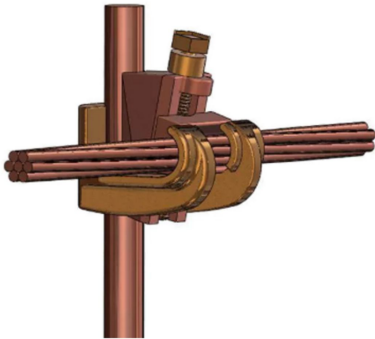

Features

- Groove A accommodates 4/0 - 250 kcmil Cu
- Groove B accommodates 4/0 - 250 kcmil Cu
- Accepts 5/8" Copper Rod

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	Yes

Conductor

Conductor - Copper Str Size A	• 4/0 AWG • 250 kcmil
Conductor - Copper Str Size B	• 4/0 AWG • 250 kcmil
Conductor - Copper Str Size A Range	4/0 AWG-250 kcmil
Conductor - Copper Solid Size A	4/0 AWG
Conductor - Copper Solid Size B	4/0 AWG
Conductor - Copper Solid Size A Range	4/0 AWG
Conductor - Copper Solid Size B Range	4/0 AWG
Conductor Type	• CU C Str-Size A • CU C Solid-Size A • CU C Str-Size B • CU C Solid-Size B

Conductor - Rod Size B Range	• Rod-Size B
Conductor - Rod Size	• 5/8 in-3/4 in • 5/8 • 3/4
Conductor - Copper Str Size B Range	4/0 AWG-250 kcmil
Conductor - Rod Size B	• 5/8 in • 3/4 in

Dimensions

Dimension - Pad Width inch	2.80 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	781810113295
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810113295
UPC 14 Digit GTIN	00781810113295

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)