


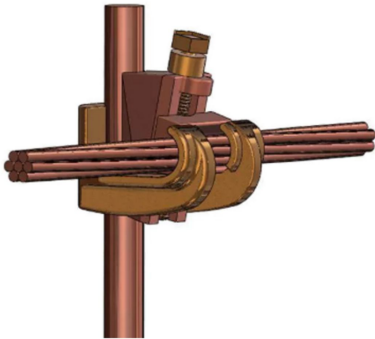

GXW2C25, GROUNDWEJ Connector, Cable to Cable

By Burndy
Catalog # [GXW2C25](#)

GROUNDWEJ Connector, Cable to Cable. Groove A: #6-#2 Cu,
Groove B: 1/0 Cu



Features

- Groove A accommodates #6- #2 Copper
- Groove B accommodates 1/0 Copper

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Certification - UL Listed Direct	No
Burial	
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Str Size B	1/0
Conductor - Copper Str Size A Range	6 AWG-2 AWG
Conductor - Copper Solid Size A	• 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG
Conductor - Copper Solid Size B	1/0 AWG
Conductor - Copper Solid Size A Range	6 AWG-2 AWG
Conductor - Copper Solid Size B Range	6 AWG-2 AWG

Conductor Type	• CU C Str-Size A • CU C Solid-Size A • CU C Str-Size B • CU C Solid-Size B • Rod-Size B
Conductor - Copper Str Size B Range	1/0

Dimensions

Dimension - Pad Width inch	2.80 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	781810441121
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810441121
UPC 14 Digit GTIN	00781810441121

Logistics

Minimum Pack Quantity	20
Pallet Quantity	1
Carton Quantity	1

Product Assets

- [Catalog \[English\]](#)
[Installation Manual \[English\]](#)