



GXW2C58, GROUNDWEJ Connector, Cable to Cable or Cable to Rod

By Burndy
Catalog # [GXW2C58](#)

GROUNDWEJ Connector, Groove A: #6-#2, Groove B: 4/0 AWG-250 kcmil, 5/8" Copper Rod

Features


- Groove A accommodates #6-#2
- Groove B accommodates 4/0-250 kcmil
- 5/8" Copper Rod

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 6 • 5 • 4 • 3 • 2
Conductor - Copper Str Size B	• 4/0 • 250
Conductor - Copper Solid Size A	• 6 • 5 • 4 • 3 • 2
Conductor - Copper Solid Size B	4/0
Conductor Type	• CU C Str-Size A

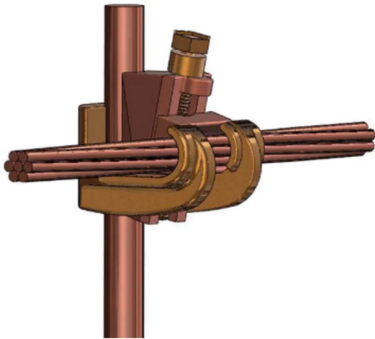

- CU C Solid-Size A
- CU C Str-Size B
- CU C Solid-Size B
- Rod-Size B

Conductor - Rod Size 5/8

Dimensions

Dimension - Pad Width inch	2.80 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	781810159491
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810159491
UPC 14 Digit GTIN	00781810159491

Logistics

Minimum Pack Quantity	10
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)