




GXW34C26, GROUNDWEJ Connector, Cable to Cable

By Burndy
Catalog # [GXW34C26](#)

GROUNDWEJ Connector, Cable to Cable. Groove A: 450-500 kcmil Copper, Groove B: 1/0-2/0 Copper

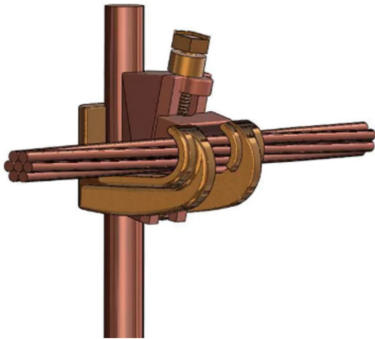

Features

- Groove A accommodates 450-500 kcmil Copper
- Groove B accommodates 1/0-2/0 Copper

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 450 • 500
Conductor - Copper Str Size B	• 1/0 • 2/0
Conductor - Copper Solid Size B	• 1/0 • 2/0
Conductor Type	• CU C Str-Size A • CU C Solid-Size A • CU C Str-Size B • CU C Solid-Size B • Rod-Size B
Conductor - Rod Size	• 1/2

• 3/4

Dimensions

Dimension - Pad Width inch	3.30 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	781810428405
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810428405
UPC 14 Digit GTIN	00781810428405

Logistics

Minimum Pack Quantity	16
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)