



GXW34C34, GROUNDWEJ Connector, Cable to Cable

By Burndy
Catalog # [GXW34C34](#)

GROUNDWEJ Connector, Cable to Cable. Groove A: 450-500 kcmil Copper, Groove B: 450-500 kcmil Copper

Features


- Groove A accommodates 450-500 kcmil Copper
- Groove B accommodates 450-500 kcmil Copper.

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Certification - UL Listed Direct	No
Burial	
Buy America(n) Qualified	Contact Manufacturer
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 450 • 500
Conductor - Copper Str Size B	• 450 • 500
Conductor Type	• CU C Str-Size A • CU C Solid-Size A • CU C Str-Size B • CU C Solid-Size B • Rod-Size B
Conductor - Rod Size	0.75

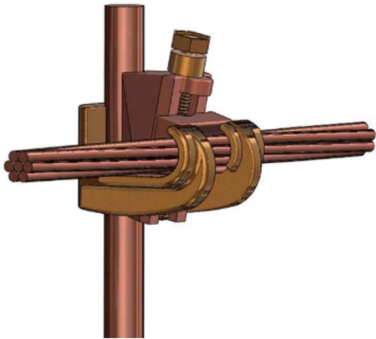

Dimensions

Dimension - Pad Width inch	3.30 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	621945740150
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	0
UPC 14 Digit GTIN	00

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

- [Catalog \[English\]](#)
[Installation Manual \[English\]](#)