




GXW34C58, GROUNDWEJ Connector, Cable to Cable

By Burndy
Catalog # [GXW34C58](#)

GROUNDWEJ Connector

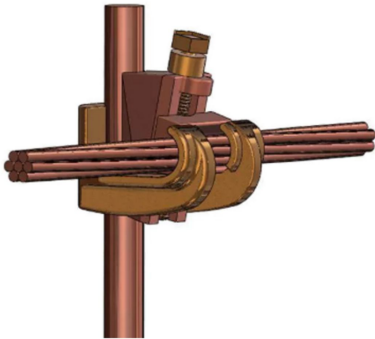

Features

- Groove A accommodates 450-500 kcmil Copper
- Groove B accommodates 4/0-250 kcmil Copper

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size A	• 300 • 350 • 400 • 450 • 500
Conductor - Copper Str Size B	• 4/0 • 250
Conductor - Copper Solid Size B	4/0
Conductor Type	• CU C Str-Size A • CU C Solid-Size A • CU C Str-Size B • CU C Solid-Size B • Rod-Size B

Conductor - Rod Size	• 1/2 • 5/8 • 3/4
----------------------	---

Dimensions

Dimension - Pad Width inch	3.30 in
Package Height	0.000 in
Dimension - Height mm	0 mm
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - B Length inch	1.80 in

General

Plated	N
Trade Name	GROUNDWEJ™
UPC	781810159507
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810159507
UPC 14 Digit GTIN	00781810159507

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[English\]](#)