



# GXW6C58, GROUNDWEJ Connector, Cable to Rod

By Burndy  
Catalog # [GXW6C58](#)

GROUNDWEJ Connector, Cable to Rod. Groove A: #12 Solid - #6 Stranded, Groove B: 5/8" Steel Rod

## Features


- Groove A accommodates #12 Sol - #6 Str
- Groove B accommodates 5/8" Steel Rod

## Specifications

|                                         |                      |
|-----------------------------------------|----------------------|
| Certification - ETL                     | No                   |
| Certification - UL Recognized           | No                   |
| Standards - RoHS Compliance Status      | EX                   |
| Certification - cULus                   | No                   |
| Certification - UL Listed Direct Burial | No                   |
| Buy America(n) Qualified                | Contact Manufacturer |
| UL Listed                               | No                   |
| Certification - CSA Approved            | No                   |

## Conductor

|                                 |                                                                                                                                |
|---------------------------------|--------------------------------------------------------------------------------------------------------------------------------|
| Conductor - Copper Str Size A   | <ul style="list-style-type: none"><li>• 12</li><li>• 10</li><li>• 9</li><li>• 8</li><li>• 7</li><li>• 6</li></ul>              |
| Conductor - Copper Solid Size A | <ul style="list-style-type: none"><li>• 12</li><li>• 11</li><li>• 10</li><li>• 9</li><li>• 8</li><li>• 7</li><li>• 6</li></ul> |
| Conductor Type                  | <ul style="list-style-type: none"><li>• CU C Str-Size A</li><li>• CU C Solid-Size A</li></ul>                                  |

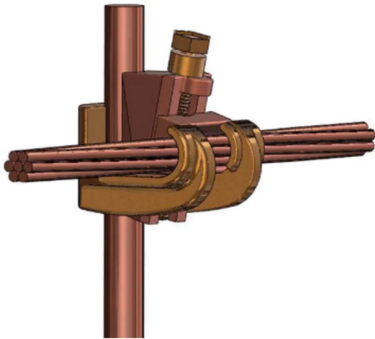

- CU C Str-Size B
- CU C Solid-Size B
- Rod-Size B

Conductor - Rod Size 5/8

## Dimensions

|                            |           |
|----------------------------|-----------|
| Dimension - Pad Width inch | 3.30 in   |
| Package Height             | 0.000 in  |
| Dimension - Height mm      | 0 mm      |
| Package Weight             | 0.000 lb. |
| Package Length             | 0.000 in  |
| Package Width              | 0.000 in  |
| Dimension - B Length inch  | 1.80 in   |

## General

|                   |              |
|-------------------|--------------|
| Plated            | N            |
| Trade Name        | GROUNDWEJ™   |
| UPC               | 621945740167 |
| Material          | Copper Alloy |
| Plating Type      | Unplated     |
| UPC 12 Digit      | 0            |
| UPC 14 Digit GTIN | 00           |

## Logistics

|                       |   |
|-----------------------|---|
| Minimum Pack Quantity | 1 |
| Pallet Quantity       | 1 |
| Carton Quantity       | 1 |

## Product Assets

[Catalog \[English\]](#)  
[Installation Manual \[English\]](#)