



GZ2612, Mechanical Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ2612](#)

Mechanical Grounding Connector, For Copper Cable to Bar, 3 AWG (Str)
- 2/0 (Str), 1/2" Stud

Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Application

For Joining A Wide Range Of Copper Cable To Bar, Direct Burial In Concrete Or Ground

Specifications


Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 3 • 2 • 1 • 1/0 • 2/0
Conductor - Copper Str Size Range	3 AWG - 2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	54.1 mm
Dimension - Height inch	2.13 in
Dimension - Height fraction	2-1/8

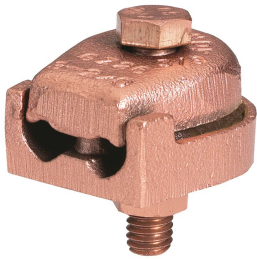

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	48 mm
Dimension - Width fraction	1-3/4 in
Dimension - Width mm	44 mm
Dimension - Width inch	1.75 in
Dimension - Length Overall inch	1.88 in

Force Related

Installation Torque Recommended	480 LBS/in in-lb
---------------------------------	------------------

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Material Type - Screw Plated	DURIUM™ Silicon Bronze No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810232125
Type	GZ
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810232125
UPC 14 Digit GTIN	00781810232125

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)