


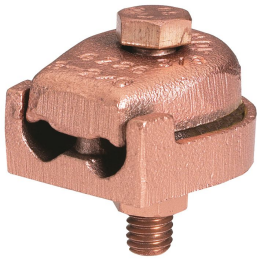

GZ6C38, Mechanical Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ2638](#)

Mechanical Grounding Connector, For Copper Cable to Bar, 3 AWG (Str) - 2/0 (Str), 3/8" Stud



Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	3 AWG - 2/0 AWG
Conductor - Copper Str Size	• 3 • 2 • 1 • 1/0 • 2/0

Dimensions

Package Height	0.000 in
Dimension - Height mm	50.8 mm
Dimension - Height inch	2.00 in

Dimension - Height fraction	2
Package Weight	0.000 lb.
Dimension - Width mm	40 mm
Dimension - Width inch	1.59 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	48 mm
Dimension - Width fraction	1-5/8 in
Dimension - Length Overall inch	1.88 in

Force Related

Installation Torque	240 LBS/in
Recommended in-lb	

General

Plated	N
UPC	781810232101
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810232101
UPC 14 Digit GTIN	00781810232101

Logistics

Minimum Pack Quantity	12
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)