



GZ2658, Mechanical Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ2658](#)

Cast Cu Alloy Ground Clamp, Cable to Bar, #3 - 2/0 AWG Str, 5/8" Bolt, Bar Thickness 1/4"

Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Application

For Joining A Wide Range Of Copper Cable To Bar, Direct Burial In Concrete Or Ground

Specifications


Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	• 3 • 2 • 1 • 1/0 • 2/0
Conductor - Copper Str Size Range	3 AWG - 2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	57.2 mm
Dimension - Height inch	2.25 in
Dimension - Height fraction	2-1/4

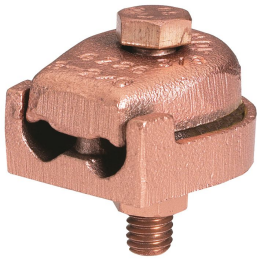

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	48 mm
Dimension - Width fraction	1-3/4 in
Dimension - Width mm	44 mm
Dimension - Width inch	1.75 in
Dimension - Length Overall inch	1.88 in

Force Related

Installation Torque Recommended	660 LBS/in in-lb
---------------------------------	------------------

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Material Type - Screw Plated	DURIUM™ Silicon Bronze No
Sub Brand	MECHANICAL CONNECTOR
Product Type	Mechanical
UPC	781810990148
Type	GZ
Construction Material - Main Material	Copper Copper
Plating Type	Unplated
UPC 12 Digit	781810990148
UPC 14 Digit GTIN	00781810990148

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)