




GZ2658T4, Mech Grounding Connector, Copper Cable to Bar

By Burndy

Catalog # [GZ2658T4](#)

Mechanical Grounding Connector, 3 AWG (Str) - 2/0 AWG (Str),
5/8" Stud, Bar Thickness 1/4" -1/2"

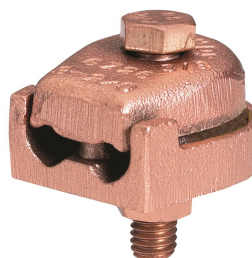

Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor Range	#3 AWG (Str) to #2/0 AWG (Str)
Conductor - Copper Str Size Range	3 AWG - 2/0 AWG
Conductor - Copper Str Size	• 3 • 2 • 1 • 1/0 • 2/0

Dimensions

Dimension - Bar Thickness mm	6 mm
Dimension - Bar Thickness inch	0.25 in
Package Height	0.000 in

Dimension - Height mm	0 mm
Dimension - Height inch	2.25 in
Package Weight	0.000 lb.
Dimension - Width mm	44 mm
Dimension - Width inch	1.75 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	48 mm
Dimension - Width fraction	1-3/4 in
Bolt Size	5/8 in
Dimension - Length Overall inch	1.88 in

Force Related

Installation Torque	660 in-lb
Recommended in-lb	

General

Plated	N
UPC	781810219911
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810219911
UPC 14 Digit GTIN	00781810219911

Logistics

Minimum Pack Quantity	12
Pallet Quantity	1
Carton Quantity	12

Product Assets

[Catalog \[English\]](#)