



GZ26G6, Mechanical Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ26G6](#)

Mechanical Grounding Connector, 3 AWG (Str) - 2/0 AWG (Str), Suitable for Direct Burial

Features


- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	3 AWG - 2/0 AWG
Conductor - Copper Str Size	• 3 • 2 • 1

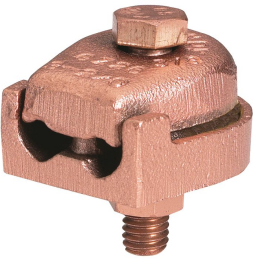

- 1/0
- 2/0

Dimensions

Dimension - Height mm	0 mm
Dimension - Width mm	32 mm
Dimension - Width inch	1.25 in
Dimension - Width fraction	1-1/4 in
Dimension - Hole Size inch	0.66 in

General

Plated	N
UPC	621945740105
Material	Copper
Plating Type	Unplated
UPC 12 Digit	0
UPC 14 Digit GTIN	00

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)