


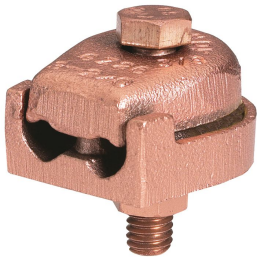

GZ2958T8, Mech Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ2958T8](#)

Mechanical Grounding Connector, 3/0 AWG (Str) - 250 kcmil, 5/8" Stud, Bar Thickness 1/2"-1"



Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Range	#3/0 AWG (Str) - 250 kcmil
Conductor - Copper Str Size Range	3/0 AWG - 250 kcmil
Conductor - Copper Str Size	• 3/0 • 4/0 • 250

Dimensions

Dimension - Bar Thickness mm	6 mm
Dimension - Bar Thickness inch	0.25 in

Dimension - Height mm	0 mm
Dimension - Height inch	2.50 in
Dimension - Width mm	55 mm
Dimension - Width inch	2.18 in
Dimension - L Length Overall mm	59 mm
Dimension - Width fraction	2-1/6 in
Bolt Size	5/8 in
Dimension - Length Overall inch	2.34 in

Force Related

Installation Torque	660 in-lb
Recommended in-lb	

General

Plated	N
UPC	781810106198
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810106198
UPC 14 Digit GTIN	00781810106198

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)



A Hubbell brand