



HSTPBK00476IPK25, Heat Shrink Tubing, Thin Wall, Black

By Burndy
Catalog # [HSTPBK00476IPK25](#)

.047" ID Min (Issued), .023" ID Max (Recovered), Thin Wall, Black, 6"
Lengths, 25 Pieces per package

Features


- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

Height 0.016 in

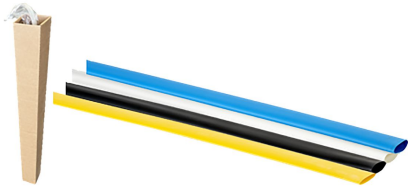

Width 0.047 in
Length 6 in
Dimensions 6 in x 0.047 in x 0.016 in

General

Product Type Polyolefin Thin Wall Heat Shrink
Color Black
UPC 621945689299

Logistics

Pallet Quantity 5040
Carton Quantity 80

Product Assets

[Catalog \[English\]](#)