



HSTPBK00944FPK25EA, Heat Shrink Tubing, Thin Wall, Black

By Burndy


Catalog # [HSTPBK00944FPK25EA](#)

.094" ID Min (Issued), .047" ID Max (Recovered), Thin Wall, Black, 4-Foot Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions

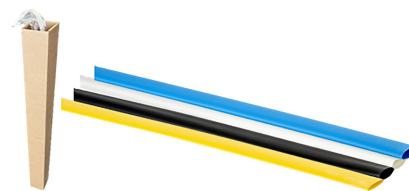

Width	0.094 in
Package Height	0.000 in
Length	48 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

Color	Black
UPC	621945699380

Product Assets

[Catalog \[English\]](#)



A Hubbell brand