




HSTPBK03756IPK25, Heat Shrink Tubing, Thin Wall, Black

By Burndy
Catalog # [HSTPBK03756IPK25](#)

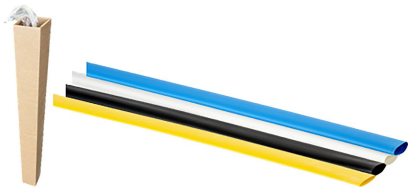

.375" ID Min (Issued), .187" ID Max (Recovered), Thin Wall, Black,
6-Inch Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions

Height	0.025 in
Width	0.375 in
Package Height	0.000 in
Length	6 in

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimensions	6 in x 0.375 in x 0.025 in

General

Color	Black
UPC	621945693944

Logistics

Pallet Quantity	960
Carton Quantity	40

Product Assets

[Catalog \[English\]](#)