



HSTPBK07506IPK25, Heat Shrink Tubing, Thin Wall, Black

By Burndy
Catalog # [HSTPBK07506IPK25](#)

.75" ID Min (Issued), .375" ID Max (Recovered), Thin Wall, Black, 6-Inch
Lengths, 25 Pieces per package

Features


- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

Height 0.03 in
Width 0.75 in
Package Height 0.000 in

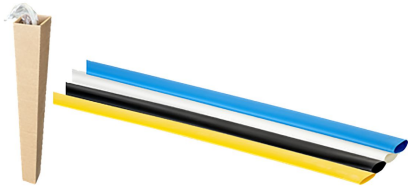

Length 6 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in
Dimensions 6 in x 0.75 in x 0.03 in

General

Product Type Polyolefin Thin Wall Heat Shrink
Color Black
UPC 621945695610

Logistics

Pallet Quantity 17250
Carton Quantity 25

Product Assets

[Catalog \[English\]](#)