



HSTPCL01876IPK25, Heat Shrink Tubing, Thin Wall, Clear

By Burndy
Catalog # [HSTPCL01876IPK25](#)


.187" ID Min (Issued), .093" ID Max (Recovered), Thin Wall, Clear,
6-Inch Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions

Height	0.02 in
Width	0.187 in

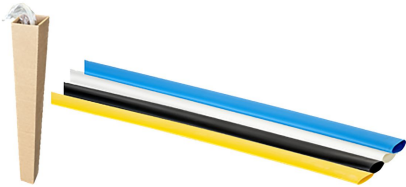

Length	6 in
Dimensions	6 in x 0.187 in x 0.02 in

General

Color	Clear
UPC	621945692756

Logistics

Pallet Quantity	1
Carton Quantity	80

Product Assets

[Catalog \[English\]](#)