



HSTPCL02504FPK25EA, Heat Shrink Tubing, Thin Wall, Clear

By Burndy

Catalog # [HSTPCL02504FPK25EA](#)

.250" ID Min (Issued), .125" ID Max (Recovered), Thin Wall, Clear,
4-Foot Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Dimensions


Width	0.25 in
Length	48 in

General

Color	Clear
UPC	621945699663

Product Assets

[Catalog \[English\]](#)

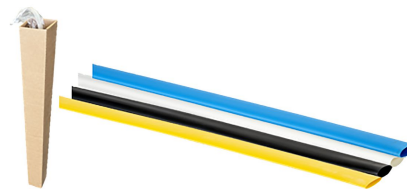

A Hubbell brand