




HSTPCL05006IPK25, Heat Shrink Tubing, Thin Wall, Clear

By Burndy
Catalog # [HSTPCL05006IPK25](#)

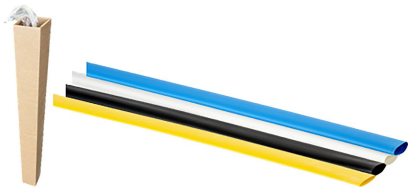

.05" ID Min (Issued), .25" ID Max (Recovered), Thin Wall, Clear, 6-Inch
Lengths, 25 Pieces per package

Features

- Ideal for industrial and automotive applications as well as covering copper and aluminum tubular connectors
- Provides mechanical protection for terminal strain relief and wire bonding
- 2:1 shrink ratio for faster shrink recovery
- Continuous Operating Temperature: -55°C to 135°C (-67°F to 275°F)
- Shrink temperature of 90°C
- Resistant to common fluids and solvents

Current

Voltage Rating 600 V

Dimensions

Height 0.025 in

Width 0.5 in
Length 6 in
Dimensions 6 in x 0.5 in x 0.025 in

General

Product Type Polyolefin Thin Wall Heat Shrink
Color Clear
UPC 621945694699

Logistics

Pallet Quantity 1008
Carton Quantity 16

Product Assets

[Catalog \[English\]](#)